
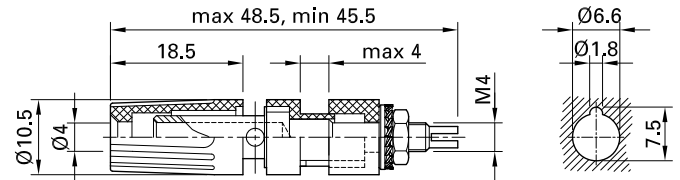


PK4-T

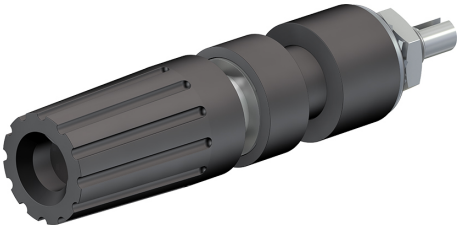

Item number 23.0330-*

Insulated, with \varnothing 4 mm rigid socket and insulated head undetachable. \varnothing 2.5 mm cross hole for quick wire connection. Machined brass. For mounting, with anti-rotation lug, in front panels up to 4 mm thick. Threaded bolt M4.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 V, 35 A / 60 V, 35 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20 21 22 23 24 25 29
Thread	M4
Test accessory acc. to	IEC EN 61010-2-030