


# SAB4-G

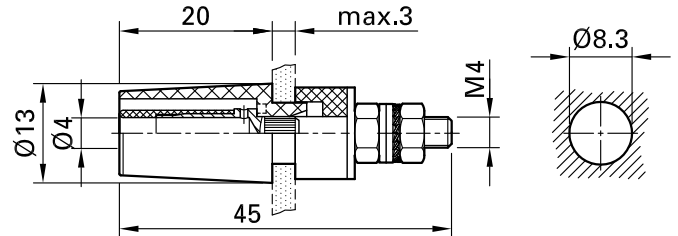

Item number 23.3050-\*

Insulated, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Machined brass. The socket is surface-mounted in pre-drilled panels of plastic, metal, etc. Threaded bolt M4.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: #90EE90; border: 1px solid black; padding: 2px;">20</span> <span style="background-color: #FF0000; border: 1px solid black; padding: 2px;">21</span> <span style="background-color: #0000FF; border: 1px solid black; padding: 2px;">22</span> <span style="background-color: #0000FF; border: 1px solid black; padding: 2px;">23</span> <span style="background-color: #FFFF00; border: 1px solid black; padding: 2px;">24</span> <span style="background-color: #008000; border: 1px solid black; padding: 2px;">25</span> <span style="background-color: #800080; border: 1px solid black; padding: 2px;">26</span> <span style="background-color: #FFA500; border: 1px solid black; padding: 2px;">27</span> <span style="background-color: #D3D3D3; border: 1px solid black; padding: 2px;">28</span> <span style="background-color: #D3D3D3; border: 1px solid black; padding: 2px;">29</span>
Thread	M4
Test accessory acc. to	IEC EN 61010-2-030
Supplied assembly material	ID-SAB4-G; U/4,3x12; 2x MU0,8D/M4; 2x U/M4; FS/M4
Remarks	Accessories: Tube spanner SS2
Approvals	UR