


# SKS4-19L/1

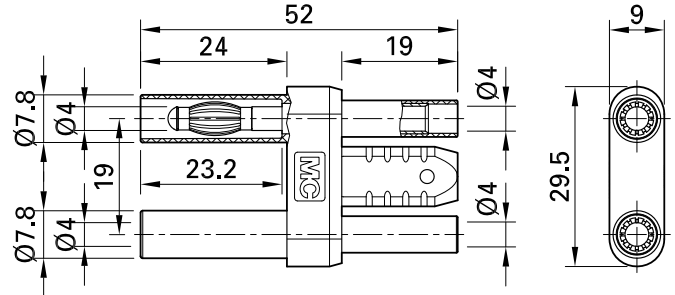

Item number 24.0028-\*

Insulated, Ø 4 mm, made of brass. Plugs with spring-loaded MULTILAM and rigid insulating sleeves. With insulated grip and with two in-line Ø 4 mm rigid sockets accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22 23
Optional color(s)	20 24 25 26 27 28 29
Plug spacing	19 mm
Test accessory acc. to	IEC EN 61010-031
User-Information	I 006
Approvals	CE