


# A-SLK4-R

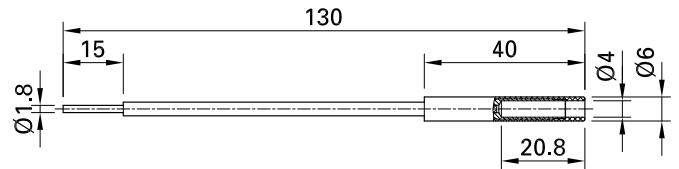

Item number 24.0162-\*

Insulated flexible copper conductor, suitable for many types of screw clamp connections, e.g., rail mounted terminals.  $\varnothing$  4 mm rigid socket in insulator, made of brass, accepting spring-loaded  $\varnothing$  4 mm plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span> <span style="background-color: blue; color: white; padding: 2px;">23</span> <span style="background-color: yellow; color: black; padding: 2px;">24</span> <span style="background-color: green; color: white; padding: 2px;">25</span> <span style="background-color: purple; color: white; padding: 2px;">26</span> <span style="background-color: brown; color: white; padding: 2px;">27</span> <span style="background-color: white; color: black; padding: 2px;">29</span>
Optional color(s)	<span style="background-color: gray; color: white; padding: 2px;">28</span>
Test accessory acc. to	IEC EN 61010-031
User-Information	I 010
Approvals	CE