


SKPS-4_100

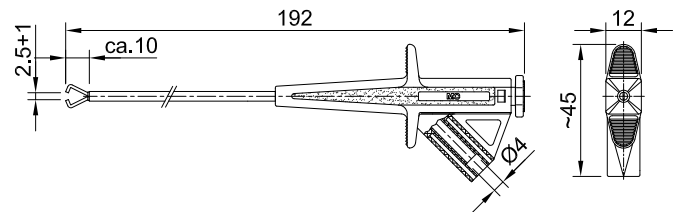

Item number 24.0227-*

With flexible shaft and spring wire grabber (stainless steel) for a good contact to pins and wires in inaccessible places. Especially suitable for measuring voltages. The shaft is silicone insulated and guarantees good heat resistance and flexibility even at low temperatures. Ø 4 mm rigid socket in handle accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 4 A
Base material electrical contact	Edelstahl
Standard color(s) *	21 22 23 24 25
Optional color(s)	26
Opening width	2.5 mm
Test accessory acc. to	IEC EN 61010-031
Approvals	UL, CE