


# AK205/405-BK

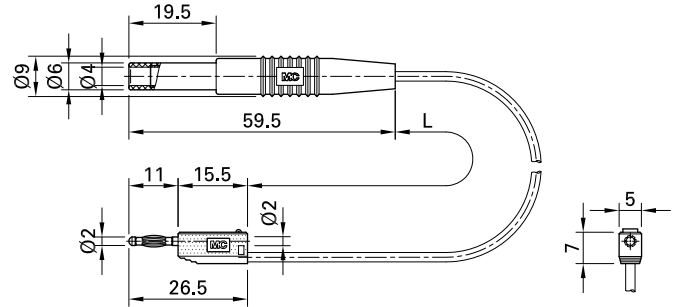

Item number 28.0012-  \*

Highly flexible. One end with Ø 2 mm stackable MULTILAM plug, the other end with Ø 4 mm rigid socket with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm / 2 mm
Rated Values	30 V, 10 A / 60 V, 10 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span>
Lead lengths <input type="text"/>	015 cm
Lead insulation	PVC
Lead cross section	0,5 mm <sup>2</sup>
Test accessory acc. to	IEC EN 61010-031
User-Information	I 093