


LK205-X

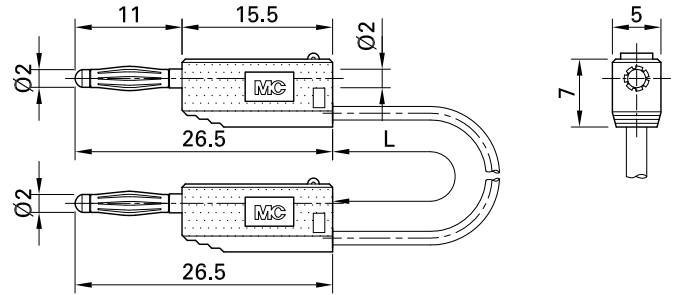

Item number 28.0115- *

Highly flexible with stackable Ø 2 mm MULTILAM plugs on both ends.

| Technical data | |
|--------------------------------------|--|
| Diameter of plug system | 2 mm |
| Rated Values | 30 V, 10 A / 60 V, 10 A |
| Surface treatment electrical contact | Ni |
| Base material electrical contact | CuZn |
| Standard color(s) * | 21 22 23 24 25 |
| Optional color(s) | 26 27 28 29 |
| Lead lengths <input type="text"/> | 007; 015; 030; 045; 060 cm |
| Lead insulation | PVC |
| Lead cross section | 0,5 mm ² |
| Test accessory acc. to | IEC EN 61010-031 |
| User-Information | I 093 |
| Approvals | CE |