


# LK-4N-F25

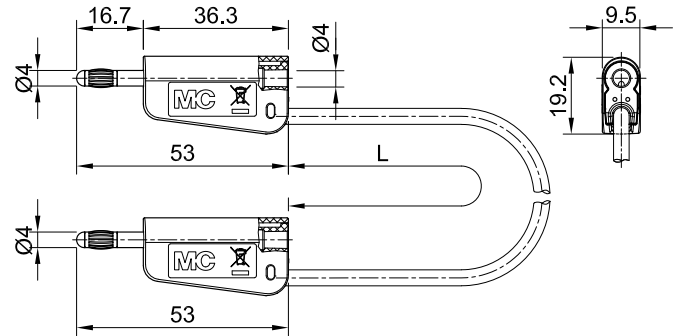

Item number 64.1034-  \*

Highly flexible, with stackable Ø 4 mm MULTILAM plugs on both ends.

| Technical data                       |   |
|--------------------------------------|---|
| Diameter of plug system              | 4 mm  |
| Rated Values                         | 30 V, 32 A / 60 V, 32 A   |
| Surface treatment electrical contact | Ni  |
| Base material electrical contact     | CuZn  |
| Standard color(s) *                  | <input type="checkbox"/> 20 <input type="checkbox"/> 21 <input type="checkbox"/> 22 <input type="checkbox"/> 23 <input type="checkbox"/> 24 <input type="checkbox"/> 25 <input type="checkbox"/> 26 <input type="checkbox"/> 27 <input type="checkbox"/> 28 <input type="checkbox"/> 29 |
| Lead lengths <input type="text"/>    | 025; 050; 075; 100; 150; 200 cm   |
| Lead insulation                      | PVC   |
| Lead cross section                   | 2,5 mm <sup>2</sup>   |
| Test accessory acc. to               | IEC EN 61010-031  |
| User-Information                     | I 099   |