


XMF-484

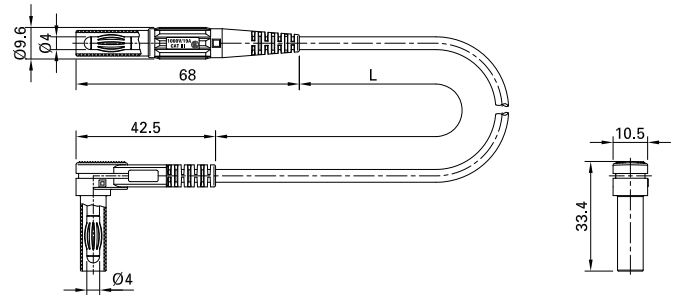

Item number 66.9005-*

Highly flexible, one end with in-line Ø 4 mm MULTILAM plug with rigid insulating sleeve. The other end with right-angled Ø 4 mm MULTILAM plug with rigid insulating sleeve.

| Technical data | |
|--------------------------------------|---|
| Diameter of plug system | 4 mm |
| Rated Values | 1000 V, CAT III, 19 A |
| Surface treatment electrical contact | Ni |
| Base material electrical contact | CuZn |
| Standard color(s) * | <input type="checkbox"/> 21 <input type="checkbox"/> 22 <input type="checkbox"/> 23 <input type="checkbox"/> 24 <input type="checkbox"/> 25 |
| Optional color(s) | <input type="checkbox"/> 20 <input type="checkbox"/> 26 <input type="checkbox"/> 27 <input type="checkbox"/> 29 |
| Lead lengths <input type="text"/> | 100; 150; 200 cm |
| Lead insulation | PVC |
| Lead cross section | 1,0 mm ² |
| Test accessory acc. to | IEC EN 61010-031 |
| Approvals | UL, CE |