


# GRIP-DI

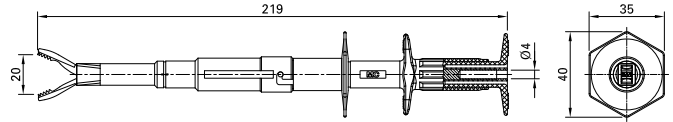

Item number 66.9266-\*

Steel jaws especially for connections to ground rails and thick cables. For increased safety when making connections, the jaws are insulated on the outside. Ø 4 mm rigid socket in handle accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Transparent fuse holder sleeve to accept a high-rating fuse 10 mm x 38 mm.

The fuse is not supplied.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT III, 16 A
Surface treatment electrical contact	Ni
Standard color(s) *	21 22
Optional color(s)	23 24 25 26
Opening width	20.0 mm
Test accessory acc. to	IEC EN 61010-031
User-Information	I 068
Remarks	Accessories: High breaking capacity fuse FLU-11
Approvals	UL, CE