


# XHL-5000

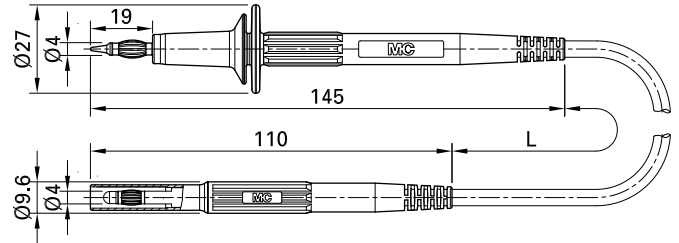

Item number 66.9426-\*

Highly flexible, one end with Ø 4 mm test probe with spring-loaded MULTILAM, the other end with in-line Ø 4 mm MULTILAM plug with rigid insulating sleeve. Supplied with protective cap.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 10 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span> <span style="background-color: blue; color: white; padding: 2px;">23</span>
Lead lengths <input type="text"/>	150 cm
Lead insulation	TPE
Lead cross section	0,5 mm <sup>2</sup>
Test accessory acc. to	IEC EN 61010-031
User-Information	I 109
Remarks	Rated voltage 5'000 V: Output voltage of test instruments, e.g. insulation testers
Approvals	CE