


XDK-1033/I-2

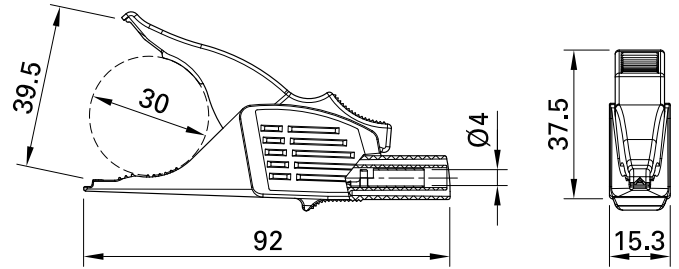

Item number 66.9561-*

Made of brass with all-round insulation. The upper jaw is non-conductive to prevent accidental short-circuits on contact with the mouth open. The insulation in this version also allows it to be used in the measurement category CAT IV.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT III, 19 A / 600 V, CAT IV, 19 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20 21 22 23 24 25 26 27 29
Optional color(s)	28
Opening width	39.5 mm
Test accessory acc. to	IEC EN 61010-031
Approvals	UL, CE