


XUB-G

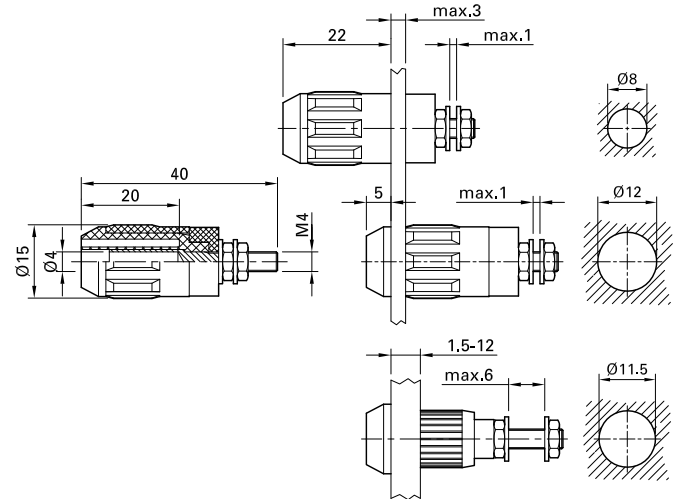

Item number 66.9684-*

Insulated, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve
 Machined brass
 The socket is surface-mounted, assembled flush, or pressed into pre-drilled panels of plastic, metal, etc
 Threaded bolt M4. Optional: Protective cap SD-XUB to cover up unplugged, unused sockets (Protection degree IP67).

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 20 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20 21 22 23 24 25 27 29
Optional color(s)	26 28
Thread	M4
Test accessory acc. to	IEC EN 61010-031
Remarks	Accessories: Protective cap SD-XUB; Press-in tool MB4-S. Other colors available on request.
Approvals	UR