
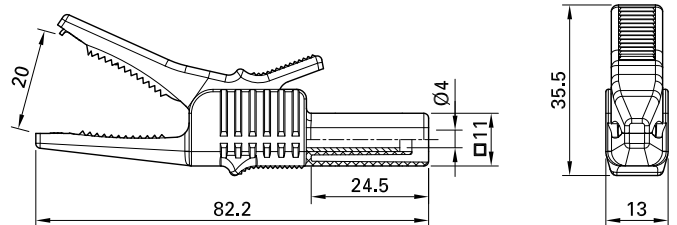


# XKK-1001

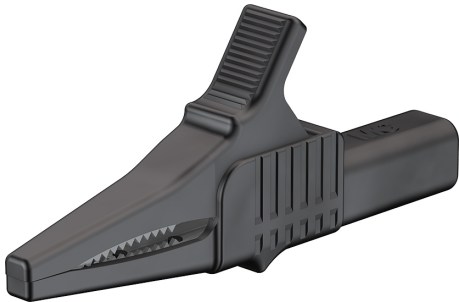

Item number 66.9755-\*

Made of brass with all-round insulation. Toothed jaws for wide grip with surface for fine wire.  $\varnothing$  4 mm rigid socket in insulator accepting spring-loaded  $\varnothing$  4 mm plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: #90EE90; border: 1px solid black; padding: 2px;">20</span> <span style="background-color: #FF0000; border: 1px solid black; padding: 2px;">21</span> <span style="background-color: #0000FF; border: 1px solid black; padding: 2px;">22</span> <span style="background-color: #0000FF; border: 1px solid black; padding: 2px;">23</span> <span style="background-color: #FFFF00; border: 1px solid black; padding: 2px;">24</span> <span style="background-color: #008000; border: 1px solid black; padding: 2px;">25</span> <span style="background-color: #800080; border: 1px solid black; padding: 2px;">26</span> <span style="background-color: #FFA500; border: 1px solid black; padding: 2px;">27</span> <span style="border: 1px solid black; padding: 2px;">29</span>
Opening width	20.0 mm
Test accessory acc. to	IEC EN 61010-031
Approvals	UL, CE