


# XLSS-58

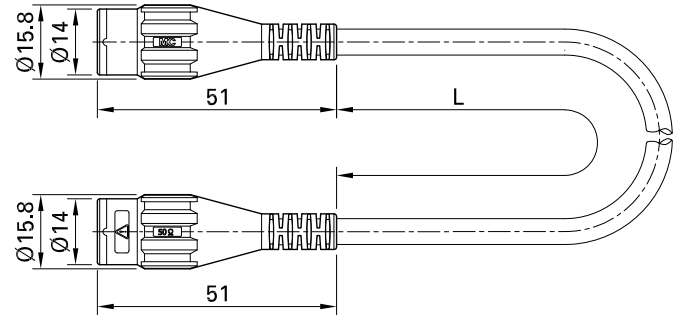

Item number 67.9770-\*

Touch-protected coaxial test leads. Version with BNC male connectors on both ends. The shield of the BNC connectors is nickel-plated, the contact pins of the inner conductor are in gold-plated brass.

Technical data	
Rated Values	1000 V, CAT II / 600 V, CAT III
Standard color(s) *	21 22 23
Lead insulation	PVC
Impedance	50.0 $\Omega$
Type coaxial lead	RG58 / PVC
Insulation coaxial lead	PVC
Temperature range coaxial lead	-10°C ... +70°C
Test accessory acc. to	IEC EN 61010-031
User-Information	I014
Approvals	UL, CE

## Cable attenuation